


BXT M4 E (920 308)


- To be plugged into BLITZDUCTOR SP / XT base parts
- Easy to use
- Quick replacement when retrofitting a protection module



Figure without obligation

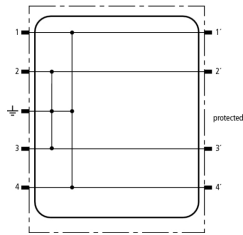

Basic circuit diagram BXT M4 E

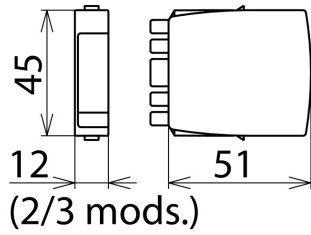

Dimension drawing BXT M4 E

The plugged-in earthing module connects all lines connected to the BLITZDUCTOR SP / XT base part to the equipotential bonding. It directly earths unused cable cores, which are already connected to the base part.

Type	BXT M4 E
Part No.	920 308
D1 Total lightning impulse current (10/350 µs) (I _{imp})	10 kA
Operating temperature range (T _U)	-40 °C ... +80 °C
Degree of protection (with plugged-in protection module)	IP 20
Plugs into	base part
Enclosure material	polyamide PA 6.6
Colour	grey ●
Weight	22 g
Customs tariff number (Comb. Nomenclature EU)	85369010
GTIN	4013364109209
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.