



KS FL30 V4A (318 233)


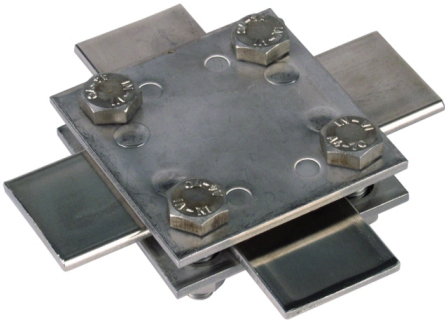



Figure without obligation

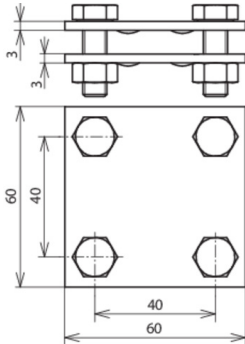

Arrangement:   

Type	KS FL30 V4A
Part No.	318 233
Material of clamp	StSt (V4A)
Clamping range FI / FI	30 / 30 mm
Screw	● M8 x 25 mm
Material of screw / nut	StSt (V4A)
Material No.	1.4571 / 1.4404 / 1.4401
ASTM / AISI:	316Ti / 316L / 316
Dimensions	60 x 60 x 3 mm
Lightning current carrying capability (10/350 μs)	 *)
Standard	EN 62561-1
Short-circuit current (AC 50 Hz / DC) (1 s; ≤ 300 °C)	7.0 kA
Weight	225 g
Customs tariff number (Comb. Nomenclature EU)	85359000
GTIN	4013364096646
PU	25 pc(s)

*) See test certificate for exact classification.

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.