

## EKV3 25IS ZK VH8QTCZ (VH8QTCZ)

- Other cable lengths can be selected online via the earthing and short-circuiting configurator

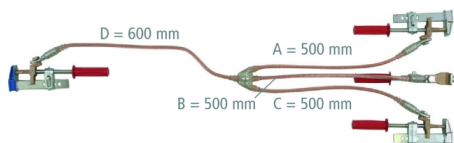


Figure without obligation



Figure without obligation

Type	EKV3 25IS ZK VH8QTCZ
Part No.	VH8QTCZ
Clamping range	55 mm
Version	Three-pole
Cable cross-section (phase side)	25 mm <sup>2</sup>
Cable cross-section (earth side)	25 mm <sup>2</sup>
Length of phase cable A	500 mm
Length of phase cable B	500 mm
Length of phase cable C	500 mm
Length of earthing cable	600 mm
Fully insulated	No
Max. short-circuit current $I_k$ 0.5 s	7.0 kA
Max. short-circuit current $I_k$ 1 s	4.9 kA
Material (clamp body)	MCl/gal Zn
Material (pressure plates)	Cu alloy
Material (short-circuiting cables)	Cu, highly flexible
Standard	EN/IEC 61230 (DIN VDE 0683-100)
Temperature range	-25 °C ... +55 °C
Weight	5,43 kg
Customs tariff number (Comb. Nomenclature EU)	85359000
GTIN	4013364163775
PU	1 pc(s)

**Attention:** Please state the relevant Variant No. when ordering.

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.

The clamp for the PEN conductor is marked in blue.