


PHE4 110 132 S 16.7 50 (783 460)

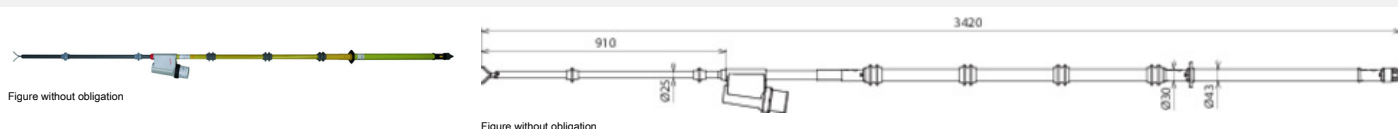

Type Part No.	PHE4 110 132 S 16.7 50 783 460
Nominal voltage (U _N)	110 ... 132 kV
Type of voltage	a.c.
Frequency	50 & 16.7 Hz
Category	S
Total length (l _Σ)	3420 mm
Insertion depth (l _o)	910 mm
Length (handle) (l _h)	780 mm
Standard	EN/IEC 61243-1 (DIN VDE 0682-411)
Temperature range	-25 °C ... +70 °C, climatic category N and W
Design	Complete
For use in wet weather conditions	Yes
For	Indoor and outdoor installations
Application	Switchgear installations and overhead lines
Design	Single-pole
Indication	Acoustic and visual
Sound level	> 67 dB(A) (visual indication and intermittent sound signal)
Self-testing element *)	yes
Battery	Lithium AA 1.5 Volt
Material (test electrode)	Copper alloy/gal Sn
Material (test prod)	Glass-fibre reinforced epoxy resin tube
Material (indicator)	Plastic, fully insulated
Material (insulating stick)	Glass-fibre reinforced polyester tube
Diameter (insulating stick)	30 mm
Weight	3,31 kg
Customs tariff number (Comb. Nomenclature EU)	90303370
GTIN	4013364309869
PU	1 pc(s)

*) all circuits without test prod

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.